



List Prices subject to change without notice  
Visit our website for the most current information.

### BRONZE Y-STRAINER — SOLDER END W/PLUG

| Fig. No.  | Size        | 1/4" | 3/8" | 1/2"     | 3/4"     | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2" | 3"  |
|---|-------------|------|------|----------|----------|-----------|-----------|-----------|-----------|--------|-----|
| <b>S-221-A</b><br>Class 125<br>20 Mesh Screen<br>w/Plug             | List Price  | N/A  | N/A  | \$ 58.92 | \$ 70.47 | \$ 98.20  | \$ 143.30 | \$ 165.30 | \$ 268.00 | N/A    | N/A |
|   | Box Qty     | —    | —    | 10       | 5        | 5         | 2         | 2         | 2         | —      | —   |
|   | Unit Wgt.   | —    | —    | .57      | 1.01     | 1.59      | 2.68      | 3.99      | 6.94      | —      | —   |
|   | Case Qty.   | —    | —    | 50       | 30       | 25        | 10        | 10        | 6         | —      | —   |
|   | UPC 039923- | —    | —    | 279927   | 279934   | 279941    | 279958    | 279965    | 279972    | —      | —   |
| <b>S-222-A</b><br>Class 125<br>Perforated Stainless Steel<br>w/Plug | List Price  | N/A  | N/A  | \$ 67.01 | \$ 78.57 | \$ 107.40 | \$ 159.50 | \$ 182.60 | \$ 296.90 | N/A    | N/A |
|   | Box Qty     | —    | —    | 10       | 5        | 5         | 2         | 2         | 2         | —      | —   |
|   | Unit Wgt.   | —    | —    | .57      | 1.01     | 1.59      | 2.68      | 3.99      | 6.94      | —      | —   |
|   | Case Qty.   | —    | —    | 50       | 30       | 25        | 10        | 10        | 6         | —      | —   |
|   | UPC 039923- | —    | —    | 280091   | 280107   | 280169    | 280176    | 280183    | 280190    | —      | —   |



### BRONZE Y-STRAINER — SOLDER END W/SOLID CAP

| Fig. No.   | Size        | 1/4" | 3/8" | 1/2"     | 3/4"     | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2" | 3"  |
|--|-------------|------|------|----------|----------|-----------|-----------|-----------|-----------|--------|-----|
| <b>S-221-B</b><br>Class 125<br>20 Mesh Screen<br>w/Solid Cap             | List Price  | N/A  | N/A  | \$ 58.92 | \$ 70.47 | \$ 99.35  | \$ 142.20 | \$ 164.00 | \$ 265.80 | N/A    | N/A |
|  | Box Qty     | —    | —    | 10       | 5        | 5         | 2         | 2         | 2         | —      | —   |
|  | Unit Wgt.   | —    | —    | .57      | 1.01     | 1.59      | 2.68      | 3.99      | 6.94      | —      | —   |
|  | Case Qty.   | —    | —    | 50       | 30       | 25        | 10        | 10        | 6         | —      | —   |
|  | UPC 039923- | —    | —    | 279989   | 279996   | 280008    | 280060    | 280077    | 280084    | —      | —   |
| <b>S-222-B</b><br>Class 125<br>Perforated Stainless Steel<br>w/Solid Cap | List Price  | N/A  | N/A  | \$ 63.55 | \$ 75.10 | \$ 105.20 | \$ 154.80 | \$ 175.70 | \$ 288.90 | N/A    | N/A |
|  | Box Qty     | —    | —    | 10       | 5        | 5         | 2         | 2         | 2         | —      | —   |
|  | Unit Wgt.   | —    | —    | .57      | 1.01     | 1.59      | 2.68      | 3.99      | 6.94      | —      | —   |
|  | Case Qty.   | —    | —    | 50       | 30       | 25        | 10        | 10        | 6         | —      | —   |
|  | UPC 039923- | —    | —    | 280206   | 280213   | 280251    | 280268    | 280275    | 280282    | —      | —   |



### BRONZE Y-STRAINER — THREADED END W/ PLUG

| Fig. No.  | Size        | 1/4"     | 3/8"     | 1/2"     | 3/4"     | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
|---|-------------|----------|----------|----------|----------|-----------|-----------|-----------|-----------|-----------|-----------|
| <b>T-221-A</b><br>Class 125<br>20 Mesh Screen<br>w/Plug             | List Price  | \$ 56.61 | \$ 56.61 | \$ 56.61 | \$ 77.41 | \$ 99.35  | \$ 138.80 | \$ 166.40 | \$ 286.50 | \$ 626.00 | \$ 854.00 |
|   | Box Qty     | 10       | 10       | 10       | 5        | 5         | 2         | 2         | 2         | 1         | 1         |
|   | Unit Wgt.   | .74      | .71      | .81      | 1.13     | 1.85      | 2.96      | 4.47      | 7.45      | 14.94     | 21.96     |
|   | Case Qty.   | 50       | 50       | 50       | 30       | 25        | 10        | 10        | 6         | 3         | 2         |
|   | UPC 039923- | 280299   | 280305   | 280312   | 280350   | 280367    | 280374    | 280381    | 280398    | 280442    | 280459    |
| <b>T-222-A</b><br>Class 125<br>Perforated Stainless Steel<br>w/Plug | List Price  | \$ 58.92 | \$ 58.92 | \$ 58.92 | \$ 83.18 | \$ 106.30 | \$ 150.30 | \$ 176.80 | \$ 306.20 | \$ 670.00 | \$ 914.00 |
|   | Box Qty     | 10       | 10       | 10       | 5        | 5         | 2         | 2         | 2         | 1         | 1         |
|   | Unit Wgt.   | .74      | .71      | .81      | 1.13     | 1.85      | 2.96      | 4.47      | 7.45      | 14.94     | 21.68     |
|   | Case Qty.   | 50       | 50       | 50       | 30       | 25        | 10        | 10        | 6         | 3         | 2         |
|   | UPC 039923- | 280619   | 280626   | 280633   | 280640   | 280657    | 280664    | 280671    | 280688    | 280695    | 280701    |

WARNING: Cancer and Reproductive Harm – www.P65Warnings.ca.gov.

**NIBCO**  
AHEAD OF THE FLOW®


**NIBCO INC.**  
**WORLD HEADQUARTERS**  
**WEB: www.nibco.com**

1516 MIDDLEBURY STREET  
ELKHART, IN 46516-4740  
USA

DOMESTIC CUSTOMER SERVICE  
PHONE: 800.234.0227  
FAX: 800.234.0557

TECHNICAL SERVICE  
PHONE: 888.446.4226  
FAX: 888.336.4226

INTERNATIONAL OFFICE  
PHONE: +1/574.295.3327  
FAX: +1/574.295.3455

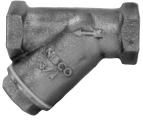

### BRONZE Y-STRAINER — THREADED END W/SOLID CAP

| Fig. No.   | Size        | 1/4"     | 3/8"     | 1/2"     | 3/4"     | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
|--|-------------|----------|----------|----------|----------|-----------|-----------|-----------|-----------|-----------|-----------|
| <b>T-221-B</b><br>Class 125<br>20 Mesh Screen<br>w/Solid Cap             | List Price  | \$ 54.30 | \$ 54.30 | \$ 54.30 | \$ 75.10 | \$ 98.20  | \$ 137.50 | \$ 164.00 | \$ 283.10 | \$ 620.00 | \$ 846.00 |
|  | Box Qty     | 10       | 10       | 10       | 5        | 5         | 2         | 2         | 2         | 1         | 1         |
|  | Unit Wgt.   | .74      | .71      | .81      | 1.13     | 1.85      | 2.96      | 4.47      | 7.45      | 14.94     | 21.68     |
|  | Case Qty.   | 50       | 50       | 50       | 30       | 25        | 10        | 10        | 6         | 3         | 2         |
|  | UPC 039923- | 280466   | 280473   | 280480   | 280497   | 280541    | 280558    | 280565    | 280572    | 280596    | 280602    |
| Fig. No.   | Size        | 1/4"     | 3/8"     | 1/2"     | 3/4"     | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
| <b>T-222-B</b><br>Class 125<br>Perforated Stainless Steel<br>w/Solid Cap | List Price  | \$ 56.61 | \$ 56.61 | \$ 56.61 | \$ 80.88 | \$ 101.70 | \$ 143.30 | \$ 169.90 | \$ 294.60 | \$ 645.00 | \$ 875.00 |
|  | Box Qty     | 10       | 10       | 10       | 5        | 5         | 2         | 2         | 2         | 1         | 1         |
|  | Unit Wgt.   | .74      | .71      | .81      | 1.13     | 1.85      | 2.96      | 4.47      | 7.45      | 14.94     | 21.68     |
|  | Case Qty.   | 50       | 50       | 50       | 30       | 25        | 10        | 10        | 6         | 3         | 2         |
|  | UPC 039923- | 280848   | 280855   | 280862   | 280879   | 280886    | 280893    | 280909    | 281029    | 281036    | 281043    |



### IRON Y-STRAINER — THREADED END

| Fig. No.  | Size        | 1/4"     | 3/8"     | 1/2"     | 3/4"     | 1"       | 1 1/4"   | 1 1/2"   | 2"        | 2 1/2"    | 3"        |
|---|-------------|----------|----------|----------|----------|----------|----------|----------|-----------|-----------|-----------|
| <b>T-751-A</b><br>Class 250<br>20 Mesh Screen<br>w/Plug | List Price  | \$ 18.48 | \$ 18.72 | \$ 18.72 | \$ 27.73 | \$ 36.97 | \$ 47.37 | \$ 65.86 | \$ 101.70 | \$ 202.30 | \$ 278.50 |
|   | Unit Wgt.   | 1.39     | 1.39     | 1.39     | 2.20     | 3.08     | 5.06     | 7.70     | 12.54     | 24.42     | 29.26     |
|   | Case Qty.   | 10       | 10       | 10       | 10       | 8        | 6        | 4        | 3         | 1         | 1         |
|   | UPC 039923- | 308498   | 308511   | 308535   | 308559   | 308573   | 308580   | 308597   | 308610    | 308634    | 308658    |



### IRON Y-STRAINER — FLANGED

| Fig. No.   | Size        | 2"        | 2 1/2"    | 3"        | 4"        | 5"        | 6"        | 8"          | 10"         | 12"         |
|--|-------------|-----------|-----------|-----------|-----------|-----------|-----------|-------------|-------------|-------------|
| <b>F-721-A</b><br>Class 125<br>Perforated Screen<br>w/Plug | List Price  | \$ 211.40 | \$ 229.90 | \$ 269.30 | \$ 409.00 | \$ 744.00 | \$ 924.00 | \$ 1,635.00 | \$ 3,028.00 | \$ 4,323.00 |
|  | Unit Wgt.   | 18.04     | 32.56     | 37.84     | 67.10     | 94.60     | 136.62    | 270.60      | 374.00      | 605.00      |
|  | Case Qty.   | 1         | 1         | 1         | 1         | 1         | 1         | 1           | 1           | 1           |
|  | UPC 039923- | 308672    | 308696    | 308702    | 308719    | 308733    | 308757    | 308771      | 308795      | 308801      |

 


### IRON Y-STRAINER — FLANGED

| Fig. No.   | Size        | 14"         | 16"          |
|--|-------------|-------------|--------------|
| <b>F-721-A</b><br>Class 125<br>Perforated Screen<br>w/Plug | List Price  | \$ 9,366.00 | \$ 13,206.00 |
|  | Box Qty     | 10          | 10           |
|  | Unit Wgt.   | 863.00      | 1380.00      |
|  | Case Qty.   | 1           | 1            |
|  | UPC 039923- | 310415      | 310422       |

**WARNING:** Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

## BRONZE REPLACEMENT PARTS



### 20 Mesh Screens

| Size        | 1/4"      | 3/8"      | 1/2"      | 3/4"      | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
|-------------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|
| List Price  | \$ 17.34  | \$ 17.34  | \$ 17.34  | \$ 17.34  | \$ 20.79  | \$ 25.42  | \$ 28.89  | \$ 49.67  | \$ 21.95  | \$ 43.91  |
| Part Number | T066957PP | T066957PP | T066957PP | T066958PP | T066959PP | T066960PP | T066961PP | T066962PP | T066963PP | T066964PP |



### Perforated Stainless Steel Screens

| Size        | 1/4"      | 3/8"      | 1/2"      | 3/4"      | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
|-------------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|
| List Price  | \$ 17.34  | \$ 17.34  | \$ 17.34  | \$ 16.19  | \$ 19.99  | \$ 19.64  | \$ 24.26  | \$ 31.20  | \$ 43.91  | \$ 57.76  |
| Part Number | T066997PP | T066997PP | T066997PP | T066998PP | T066999PP | T067000PP | T067001PP | T067002PP | T067003PP | T067004PP |

### PTFE Bonnet Gasket

 
| Size        | 1/4"      | 3/8"      | 1/2"      | 3/4"      | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
|-------------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|
| List Price  | \$ 0.59   | \$ 0.59   | \$ 0.59   | \$ 0.59   | \$ 1.63   | \$ 2.08   | \$ 2.67   | \$ 3.12   | \$ 7.39   | \$ 12.72  |
| Part Number | T066965PP | T066965PP | T066965PP | T066966PP | T066967PP | T066968PP | T066969PP | T066970PP | T066971PP | T066972PP |

### NPT Plug

| Size        | 1/4"      | 3/8"      | 1/2"      | 3/4"      | 1"        | 1 1/4"    | 1 1/2"    | 2"        | 2 1/2"    | 3"        |
|-------------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|-----------|
| List Price  | \$ 1.63   | \$ 1.63   | \$ 1.63   | \$ 1.63   | \$ 2.43   | \$ 4.98   | \$ 4.98   | \$ 5.08   | \$ 11.22  | \$ 18.48  |
| Part Number | T067044PP | T067044PP | T067044PP | T067045PP | T067045PP | E177050FC | E177050FC | E177100FC | E177150FC | E177200FC |

⚠ **WARNING:** Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

## IRON REPLACEMENT PARTS



### T-751-A — 20 Mesh (1/4" - 2"), 1/16" Perforated (2 1/2" - 3") Stainless Steel Screens

| Size        | 1/4"    | 3/8"    | 1/2"    | 3/4"    | 1"      | 1 1/4"  | 1 1/2"  | 2"      | 2 1/2"   | 3"       |
|-------------|---------|---------|---------|---------|---------|---------|---------|---------|----------|----------|
| List Price  | \$ 2.20 | \$ 2.20 | \$ 2.20 | \$ 2.78 | \$ 3.01 | \$ 3.47 | \$ 3.94 | \$ 4.98 | \$ 30.04 | \$ 40.44 |
| Part Number | RG60009 | RG60010 | RG60011 | RG60012 | RG60013 | RG60014 | RG60015 | RG60016 | RG60017  | RG60018  |



### F-721-A — 1/16" Perforated (2" - 4"), 1/8" Perforated (5" - 16") Stainless Steel Screens

| Size        | 2"       | 2 1/2"   | 3"       | 4"       | 5"        | 6"        | 8"        | 10"       | 12"       | 14"       | 16"         |
|-------------|----------|----------|----------|----------|-----------|-----------|-----------|-----------|-----------|-----------|-------------|
| List Price  | \$ 24.26 | \$ 31.20 | \$ 35.81 | \$ 56.61 | \$ 112.20 | \$ 184.80 | \$ 269.30 | \$ 390.50 | \$ 564.00 | \$ 891.00 | \$ 1,228.00 |
| Part Number | RG60019  | RG60020  | RG60021  | RG60022  | RG60023   | RG60024   | RG60025   | RG60026   | RG60027   | RG60028   | RG60029     |

### T-751-A — Metal-Filled Graphite Bonnet Gasket

| Size        | 1/4"    | 3/8"    | 1/2"    | 3/4"    | 1"      | 1 1/4"  | 1 1/2"  | 2"      | 2 1/2"  | 3"      |
|-------------|---------|---------|---------|---------|---------|---------|---------|---------|---------|---------|
| List Price  | \$ 1.85 | \$ 1.85 | \$ 1.85 | \$ 2.20 | \$ 2.43 | \$ 2.78 | \$ 3.35 | \$ 4.52 | \$ 5.55 | \$ 6.02 |
| Part Number | RG60030 | RG60031 | RG60032 | RG60033 | RG60034 | RG60035 | RG60036 | RG60037 | RG60038 | RG60039 |

### F-721-A — Metal-Filled Graphite Bonnet Gasket

| Size        | 2"      | 2 1/2"  | 3"      | 4"      | 5"       | 6"       | 8"       | 10"      | 12"      |
|-------------|---------|---------|---------|---------|----------|----------|----------|----------|----------|
| List Price  | \$ 4.63 | \$ 6.02 | \$ 6.59 | \$ 8.90 | \$ 12.13 | \$ 17.34 | \$ 19.64 | \$ 21.95 | \$ 28.89 |
| Part Number | RG60040 | RG60041 | RG60042 | RG60043 | RG60044  | RG60045  | RG60046  | RG60047  | RG60048  |

### T-751-A — Iron NPT Plug

| Size        | 1/4"    | 3/8"    | 1/2"    | 3/4"    | 1"      | 1 1/4"  | 1 1/2"  | 2"      | 2 1/2"  | 3"      |
|-------------|---------|---------|---------|---------|---------|---------|---------|---------|---------|---------|
| List Price  | \$ 3.82 | \$ 3.82 | \$ 3.82 | \$ 3.82 | \$ 3.82 | \$ 4.63 | \$ 4.63 | \$ 6.13 | \$ 6.13 | \$ 9.13 |
| Part Number | RG60001 | RG60001 | RG60001 | RG60002 | RG60002 | RG60004 | RG60004 | RG60005 | RG60005 | RG60006 |

### F-721-A — Iron NPT Plug

| Size        | 2"      | 2 1/2"  | 3"      | 4"       | 5"       | 6"       | 8"       | 10"      | 12"      |
|-------------|---------|---------|---------|----------|----------|----------|----------|----------|----------|
| List Price  | \$ 3.82 | \$ 6.13 | \$ 6.13 | \$ 10.74 | \$ 15.03 | \$ 15.03 | \$ 15.03 | \$ 15.03 | \$ 15.03 |
| Part Number | RG60003 | RG60005 | RG60005 | RG60007  | RG60008  | RG60008  | RG60008  | RG60008  | RG60008  |

⚠ **WARNING:** Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**NIBCO**<sup>®</sup>  
AHEAD OF THE FLOW<sup>®</sup>

**NIBCO INC.**  
**WORLD HEADQUARTERS**  
**WEB:** [www.nibco.com](http://www.nibco.com)

1516 MIDDLEBURY STREET  
ELKHART, IN 46516-4740  
USA

DOMESTIC CUSTOMER SERVICE  
PHONE: 800.234.0227  
FAX: 800.234.0557

TECHNICAL SERVICE  
PHONE: 888.446.4226  
FAX: 888.336.4226

INTERNATIONAL OFFICE  
PHONE: +1/574.295.3327  
FAX: +1/574.295.3455