



List Prices subject to change without notice  
Visit our website for the most current information.

### BRONZE Y-STRAINER — SOLDER END W/PLUG

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
<b>S-221-A</b> Class 125 20 Mesh Screen w/Plug	List Price	N/A	N/A	\$ 67.01	\$ 79.79	\$ 111.60	\$ 162.90	\$ 187.60	\$ 303.10	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	279927	279934	279941	279958	279965	279972	—	—
<b>S-222-A</b> Class 125 Perforated Stainless Steel w/Plug	List Price	N/A	N/A	\$ 76.60	\$ 89.28	\$ 121.20	\$ 181.40	\$ 206.20	\$ 336.10	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	280091	280107	280169	280176	280183	280190	—	—



### BRONZE Y-STRAINER — SOLDER END W/SOLID CAP

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
<b>S-221-B</b> Class 125 20 Mesh Screen w/Solid Cap	List Price	N/A	N/A	\$ 67.01	\$ 79.79	\$ 112.70	\$ 160.80	\$ 186.60	\$ 301	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	279989	279996	280008	280060	280077	280084	—	—
<b>S-222-B</b> Class 125 Perforated Stainless Steel w/Solid Cap	List Price	N/A	N/A	\$ 72.37	\$ 85.05	\$ 119.10	\$ 176.30	\$ 199.00	\$ 326.80	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	280206	280213	280251	280268	280275	280282	—	—



### BRONZE Y-STRAINER — THREADED END W/ PLUG

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
<b>T-221-A</b> Class 125 20 Mesh Screen w/Plug	List Price	\$ 64.85	\$ 64.85	\$ 64.85	\$ 88.25	\$ 112.70	\$ 157.30	\$ 188.70	\$ 324.70	\$ 707	\$ 965
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.96
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280299	280305	280312	280350	280367	280374	280381	280398	280442	280459
<b>T-222-A</b> Class 125 Perforated Stainless Steel w/Plug	List Price	\$ 67.01	\$ 67.01	\$ 67.01	\$ 94.64	\$ 120.10	\$ 170.10	\$ 200.00	\$ 347.40	\$ 756	\$ 1,033
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.68
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280619	280626	280633	280640	280657	280664	280671	280688	280695	280701

WARNING: Cancer and Reproductive Harm – www.P65Warnings.ca.gov.

**NIBCO**  
AHEAD OF THE FLOW®


**NIBCO INC.**  
**WORLD HEADQUARTERS**  
WEB: [www.nibco.com](http://www.nibco.com)

1516 MIDDLEBURY STREET  
ELKHART, IN 46516-4740  
USA

DOMESTIC CUSTOMER SERVICE  
PHONE: 800.234.0227  
FAX: 800.234.0557

TECHNICAL SERVICE  
PHONE: 888.446.4226  
FAX: 888.336.4226

INTERNATIONAL OFFICE  
PHONE: +1/574.295.3327  
FAX: +1/574.295.3455

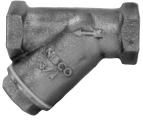

### BRONZE Y-STRAINER — THREADED END W/SOLID CAP

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
<b>T-221-B</b> Class 125 20 Mesh Screen w/Solid Cap	List Price	\$ 61.65	\$ 61.65	\$ 61.65	\$ 85.05	\$ 111.60	\$ 155.30	\$ 186.60	\$ 320.60	\$ 700	\$ 955
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.68
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280466	280473	280480	280497	280541	280558	280565	280572	280596	280602
Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
<b>T-222-B</b> Class 125 Perforated Stainless Steel w/Solid Cap	List Price	\$ 64.85	\$ 64.85	\$ 64.85	\$ 91.44	\$ 114.80	\$ 162.90	\$ 192.80	\$ 333	\$ 729	\$ 988
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.68
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280848	280855	280862	280879	280886	280893	280909	281029	281036	281043



### IRON Y-STRAINER — THREADED END

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
<b>T-751-A</b> Class 250 20 Mesh Screen w/Plug	List Price	\$ 25.46	\$ 25.46	\$ 25.46	\$ 37.53	\$ 49.59	\$ 64.43	\$ 89.07	\$ 136	\$ 270.10	\$ 371.10
	Unit Wgt.	1.39	1.39	1.39	2.20	3.08	5.06	7.70	12.54	24.42	29.26
	Case Qty.	10	10	10	10	8	6	4	3	1	1
	UPC 039923-	308498	308511	308535	308559	308573	308580	308597	308610	308634	308658



### IRON Y-STRAINER — FLANGED

Fig. No.	Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"
<b>F-721-A</b> Class 125 Perforated Screen w/Plug	List Price	\$ 281.40	\$ 306.20	\$ 358.80	\$ 544	\$ 990	\$ 1,228	\$ 2,172	\$ 4,024	\$ 5,743
	Unit Wgt.	18.04	32.56	37.84	67.10	94.60	136.62	270.60	374	605
	Case Qty.	1	1	1	1	1	1	1	1	1
	UPC 039923-	308672	308696	308702	308719	308733	308757	308771	308795	308801




### IRON Y-STRAINER — FLANGED

Fig. No.	Size	14"	16"
<b>F-721-A</b> Class 125 Perforated Screen w/Plug	List Price	\$ 12,454	\$ 17,550
	Box Qty	10	10
	Unit Wgt.	863	1380
	Case Qty.	1	1
	UPC 039923-	310415	310422

**WARNING:** Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).
 
## BRONZE REPLACEMENT PARTS



### 20 Mesh Screens

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 19.69	\$ 19.69	\$ 19.69	\$ 19.69	\$ 23.51	\$ 28.76	\$ 32.68	\$ 56.39	\$ 24.95	\$ 49.69
Part Number	T066957PP	T066957PP	T066957PP	T066958PP	T066959PP	T066960PP	T066961PP	T066962PP	T066963PP	T066964PP



### Perforated Stainless Steel Screens

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 19.69	\$ 19.69	\$ 19.69	\$ 18.35	\$ 22.68	\$ 22.27	\$ 27.42	\$ 35.36	\$ 49.69	\$ 65.98
Part Number	T066997PP	T066997PP	T066997PP	T066998PP	T066999PP	T067000PP	T067001PP	T067002PP	T067003PP	T067004PP

### PTFE Bonnet Gasket

 
Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 0.82	\$ 0.82	\$ 0.82	\$ 0.82	\$ 1.96	\$ 2.47	\$ 3.09	\$ 3.71	\$ 8.45	\$ 14.54
Part Number	T066965PP	T066965PP	T066965PP	T066966PP	T066967PP	T066968PP	T066969PP	T066970PP	T066971PP	T066972PP

### NPT Plug

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 1.96	\$ 1.96	\$ 1.96	\$ 1.96	\$ 2.78	\$ 5.67	\$ 5.67	\$ 5.77	\$ 12.78	\$ 21.03
Part Number	T067044PP	T067044PP	T067044PP	T067045PP	T067045PP	E177050FC	E177050FC	E177100FC	E177150FC	E177200FC

⚠ **WARNING:** Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

## IRON REPLACEMENT PARTS



### T-751-A — 20 Mesh (1/4" - 2"), 1/16" Perforated (2 1/2" - 3") Stainless Steel Screens

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 3.71	\$ 3.71	\$ 3.71	\$ 4.95	\$ 4.95	\$ 4.95	\$ 6.19	\$ 7.32	\$ 41.13	\$ 54.43
Part Number	RG60009	RG60010	RG60011	RG60012	RG60013	RG60014	RG60015	RG60016	RG60017	RG60018



### F-721-A — 1/16" Perforated (2" - 4"), 1/8" Perforated (5" - 16") Stainless Steel Screens

Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"	14"	16"
List Price	\$ 32.78	\$ 42.37	\$ 48.45	\$ 76.19	\$ 150.00	\$ 246.40	\$ 358.80	\$ 520	\$ 751	\$ 1,184	\$ 1,632
Part Number	RG60019	RG60020	RG60021	RG60022	RG60023	RG60024	RG60025	RG60026	RG60027	RG60028	RG60029

### T-751-A — Metal-Filled Graphite Bonnet Gasket

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 3.71	\$ 3.71	\$ 3.71	\$ 3.71	\$ 3.71	\$ 4.95	\$ 4.95	\$ 6.19	\$ 8.56	\$ 8.56
Part Number	RG60030	RG60031	RG60032	RG60033	RG60034	RG60035	RG60036	RG60037	RG60038	RG60039

### F-721-A — Metal-Filled Graphite Bonnet Gasket

Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"
List Price	\$ 7.32	\$ 8.56	\$ 9.79	\$ 12.27	\$ 17.01	\$ 24.33	\$ 26.60	\$ 30.31	\$ 38.66
Part Number	RG60040	RG60041	RG60042	RG60043	RG60044	RG60045	RG60046	RG60047	RG60048

### T-751-A — Iron NPT Plug

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 6.19	\$ 6.19	\$ 6.19	\$ 6.19	\$ 6.19	\$ 7.32	\$ 7.32	\$ 8.56	\$ 8.56	\$ 13.40
Part Number	RG60001	RG60001	RG60001	RG60002	RG60002	RG60004	RG60004	RG60005	RG60005	RG60006

### F-721-A — Iron NPT Plug

Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"
List Price	\$ 6.19	\$ 8.56	\$ 8.56	\$ 14.54	\$ 20.62	\$ 20.62	\$ 20.62	\$ 20.62	\$ 20.62
Part Number	RG60003	RG60005	RG60005	RG60007	RG60008	RG60008	RG60008	RG60008	RG60008

⚠ **WARNING:** Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**NIBCO**<sup>®</sup>  
AHEAD OF THE FLOW<sup>®</sup>

**NIBCO INC.**  
**WORLD HEADQUARTERS**  
**WEB:** [www.nibco.com](http://www.nibco.com)

1516 MIDDLEBURY STREET  
ELKHART, IN 46516-4740  
USA

DOMESTIC CUSTOMER SERVICE  
PHONE: 800.234.0227  
FAX: 800.234.0557

TECHNICAL SERVICE  
PHONE: 888.446.4226  
FAX: 888.336.4226

INTERNATIONAL OFFICE  
PHONE: +1/574.295.3327  
FAX: +1/574.295.3455